


## Truss-head bolt with flange nut

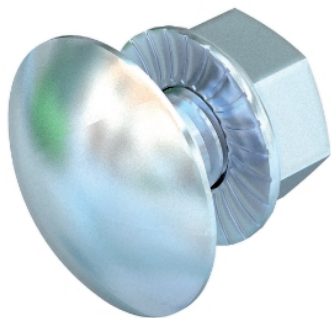

Hot galvanised truss-head bolt with square neck including electrogalvanised combination nut.

For universal fastening of construction components. Permitted use of the article only in dry atmospheres.

Type	Dimension mm	Dimen- sion L mm	Dimen- sion D mm	Pack. pcs	Weight kg/100 pcs.	Item No.
FRSB 6x12 VZ G	M 6 x 12	12	13,5	10	0,700	6406133
FRSB 6x12 G	M 6 x 12	12	13,5	100	0,796	6406130
FRSB 6x20 G	M 6 x 20	20	13,5	100	0,903	6406181
FRSB 6x12 VZ F	M 6 x 12	12	13,5	10	0,840	6406125
FRSB 6x12 F	M 6 x 12	12	13,5	100	0,990	6406122
FRSB 6x15 F	M 6 x 15	15	13,5	100	0,800	6406157
FRSB 6x20 F	M 6 x 20	20	13,5	100	1,000	6406203
FRSB 6x30 F	M 6 x 30	30	13,5	100	1,200	6406907

**St** Steel

**F** Hot-dip galvanised

**G** Electrogalvanised

### Dimensions

