


Magic straight connector set

The optimised design means that the connector can be used to create radii and as a length compensation piece for large temperature deviations.
Cable tray connector with quick fastening for the screwless connection of perforated cable trays with a side height of 60 mm.



Dimensions

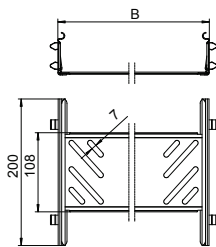

Type	Side height mm	Width mm	Pack. pcs	Weight kg/100 pcs.	Item No.
KTSMV 610 FS	60	100	1	30,500	6068914
KTSMV 615 FS	60	150	1	34,900	6068916
KTSMV 620 FS	60	200	1	37,200	6068918
KTSMV 630 FS	60	300	1	44,000	6068920
KTSMV 640 FS	60	400	1	50,700	6068922
KTSMV 650 FS	60	500	1	57,400	6068924
KTSMV 660 FS	60	600	1	64,200	6068926
KTSMV 610 DD	60	100	1	30,500	6068936
KTSMV 615 DD	60	150	1	34,900	6068938
KTSMV 620 DD	60	200	1	37,200	6068940
KTSMV 630 DD	60	300	1	44,000	6068942
KTSMV 640 DD	60	400	1	50,700	6068944
KTSMV 650 DD	60	500	1	57,400	6068946
KTSMV 660 DD	60	600	1	64,200	6068948
KTSMV 610 VA4301	60	100	1	30,500	6068958
KTSMV 615 VA4301	60	150	1	34,900	6068960
KTSMV 620 VA4301	60	200	1	37,200	6068962
KTSMV 630 VA4301	60	300	1	44,000	6068964
KTSMV 640 VA4301	60	400	1	50,700	6068966
KTSMV 650 VA4301	60	500	1	57,400	6068968
KTSMV 660 VA4301	60	600	1	64,200	6068970
KTSMV 610 VA4571	60	100	1	30,500	6068980
KTSMV 615 VA4571	60	150	1	34,900	6068982
KTSMV 620 VA4571	60	200	1	37,200	6068984
KTSMV 630 VA4571	60	300	1	44,000	6068986
KTSMV 640 VA4571	60	400	1	50,700	6068988
KTSMV 650 VA4571	60	500	1	57,400	6068990
KTSMV 660 VA4571	60	600	1	64,200	6068992

St Steel V2A Stainless steel, grade 304 V4A Stainless steel, grade 316 Ti

FS Strip-galvanised DD Strip galvanised zinc/aluminium, Double Dip