
 
 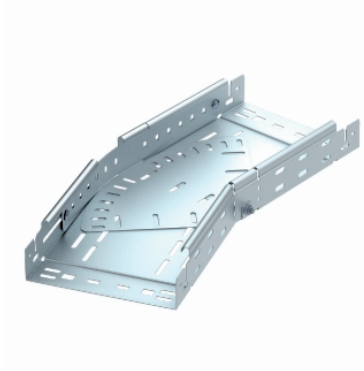


## Magic bend, variable



Dimensions



Magic bend 0°–90°, variable, with quick connector system. For all cable tray types of 60 mm side height.

Type	Width mm	Dimen- sion L mm	Plate thickness mm	Pack. pcs	Weight kg/100 pcs.	Item No.
RBMV 610 FS	100	340	1	1	76,400	6040480
RBMV 615 FS	150	420	1	1	117,100	6040482
RBMV 620 FS	200	490	1	1	163,600	6040484
RBMV 630 FS	300	640	1,25	1	291,700	6040486
RBMV 640 FS	400	820	1,25	1	578,000	6040488
RBMV 650 FS	500	960	1,5	1	986,000	6040490
RBMV 660 FS	600	1120	1,5	1	1347,200	6040492
RBMV 610 FT	100	340	1	1	83,700	6040500
RBMV 615 FT	150	420	1	1	128,900	6040502
RBMV 620 FT	200	490	1	1	179,500	6040504
RBMV 630 FT	300	640	1,25	1	386,300	6040506
RBMV 640 FT	400	820	1,25	1	635,200	6040508
RBMV 650 FT	500	960	1,5	1	1083,700	6040510
RBMV 660 FT	600	1120	1,5	1	1480,900	6040512
RBMV 610 VA 4301	100	340	1	1	76,400	6040520
RBMV 620 VA 4301	200	490	1	1	163,600	6040524
RBMV 630 VA 4301	300	640	1,25	1	386,300	6040526
RBMV 640 VA 4301	400	820	1,25	1	578,000	6040528
RBMV 650 VA 4301	500	960	1,5	1	986,000	6040530
RBMV 660 VA 4301	600	1120	1,5	1	1347,200	6040532
RBMV 610 VA 4571	100	340	1	1	76,100	6040540
RBMV 615 VA 4571	150	420	1	1	117,100	6040542
RBMV 620 VA 4571	200	490	1	1	163,200	6040544
RBMV 630 VA 4571	300	640	1,25	1	360,200	6040546
RBMV 640 VA 4571	400	820	1,25	1	577,600	6040548
RBMV 650 VA 4571	500	960	1,5	1	985,600	6040550
RBMV 660 VA 4571	600	1120	1,5	1	1346,800	6040552

St Steel V2A Stainless steel, grade 304 V4A Stainless steel, grade 316 Ti

FS Strip-galvanised FT Hot-dip galvanised