



90° Magic bend

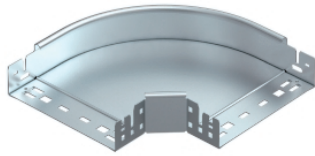

Dimensions

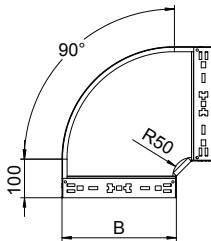

90° bend with quick connector system. For all cable tray types of 60 mm side height.

| Type | Width mm | Pack. pcs | Weight kg/100 pcs. | Item No. |
|------------------|-------------|--------------|-----------------------|----------|
| RBM 90 610 FS | 100 | 1 | 65,700 | 6041130 |
| RBM 90 615 FS | 150 | 1 | 92,000 | 6041132 |
| RBM 90 620 FS | 200 | 1 | 122,100 | 6041134 |
| RBM 90 630 FS | 300 | 1 | 192,800 | 6041136 |
| RBM 90 640 FS | 400 | 1 | 275,400 | 6041138 |
| RBM 90 650 FS | 500 | 1 | 377,200 | 6041140 |
| RBM 90 660 FS | 600 | 1 | 494,300 | 6041142 |
| RBM 90 610 FT | 100 | 1 | 70,500 | 6041150 |
| RBM 90 615 FT | 150 | 1 | 98,700 | 6041152 |
| RBM 90 620 FT | 200 | 1 | 130,900 | 6041154 |
| RBM 90 630 FT | 300 | 1 | 206,800 | 6041156 |
| RBM 90 640 FT | 400 | 1 | 295,300 | 6041158 |
| RBM 90 650 FT | 500 | 1 | 404,500 | 6041160 |
| RBM 90 660 FT | 600 | 1 | 530,100 | 6041162 |
| RBM 90 610VA4301 | 100 | 1 | 65,700 | 6041180 |
| RBM 90 615VA4301 | 150 | 1 | 92,000 | 6041182 |
| RBM 90 620VA4301 | 200 | 1 | 122,100 | 6041184 |
| RBM 90 630VA4301 | 300 | 1 | 192,800 | 6041186 |
| RBM 90 640VA4301 | 400 | 1 | 275,400 | 6041188 |
| RBM 90 650VA4301 | 500 | 1 | 377,200 | 6041190 |
| RBM 90 660VA4301 | 600 | 1 | 494,300 | 6041192 |
| RBM 90 610VA4571 | 100 | 1 | 65,700 | 6041200 |
| RBM 90 615VA4571 | 150 | 1 | 92,000 | 6041202 |
| RBM 90 620VA4571 | 200 | 1 | 122,100 | 6041204 |
| RBM 90 630VA4571 | 300 | 1 | 192,800 | 6041206 |
| RBM 90 640VA4571 | 400 | 1 | 275,400 | 6041208 |
| RBM 90 650VA4571 | 500 | 1 | 377,200 | 6041210 |
| RBM 90 660VA4571 | 600 | 1 | 494,300 | 6041212 |

St Steel V2A Stainless steel, grade 304 V4A Stainless steel, grade 316 Ti

FS Strip-galvanised FT Hot-dip galvanised