


Adjustable vertical bend element

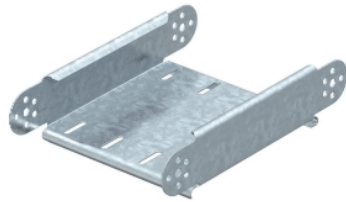


Adjustable vertical bend element, for all cable tray types with a side height of 60 mm.

Type	Width mm	Pack. pcs	Weight kg/100 pcs.	Item No.
RGBEV 610 FS	100	1	48,100	7005326
RGBEV 615 FS	150	1	63,700	7005334
RGBEV 620 FS	200	1	63,600	7005342
RGBEV 630 FS	300	1	80,400	7005369
RGBEV 640 FS	400	1	114,000	7005385
RGBEV 650 FS	500	1	134,000	7005407
RGBEV 660 FS	600	1	155,900	7005423
RGBEV 610 FT	100	1	52,400	7075103
RGBEV 615 FT	150	1	60,300	7075154
RGBEV 620 FT	200	1	69,300	7075200
RGBEV 630 FT	300	1	87,600	7075308
RGBEV 640 FT	400	1	123,000	7075405
RGBEV 650 FT	500	1	144,000	7075502
RGBEV 660 FT	600	1	167,200	7075596


St Steel
FS Strip-galvanised **FT** Hot-dip galvanised

Dimensions

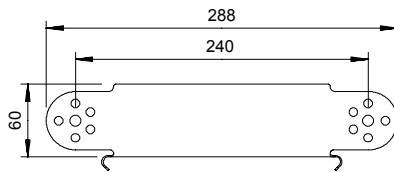

Type	Width mm	Plate thickness mm
RGBEV 610 FS	100	1
RGBEV 615 FS	150	1
RGBEV 620 FS	200	1
RGBEV 630 FS	300	1
RGBEV 640 FS	400	1
RGBEV 650 FS	500	1
RGBEV 660 FS	600	1
RGBEV 610 FT	100	1
RGBEV 615 FT	150	1
RGBEV 620 FT	200	1
RGBEV 630 FT	300	1
RGBEV 640 FT	400	1
RGBEV 650 FT	500	1
RGBEV 660 FT	600	1

Installation

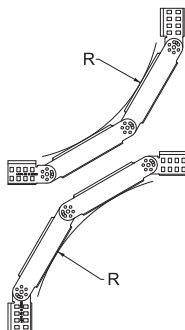

Radius table

Anzahl Elemente	Radius
1	ca. 300 mm
2	ca. 450 mm
3	ca. 600 mm
4	ca. 750 mm
5	ca. 900 mm

Please order two LGVG 60 articulated connectors separately.