



Cover

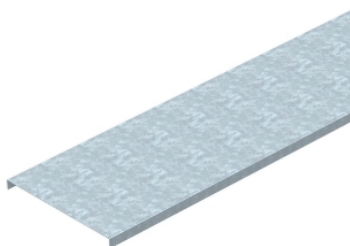

Dimensions

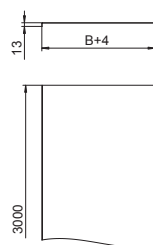

When using covers outdoors, additional measures against the influence of wind must be taken.

Cover for cable trays and mesh cable trays.

Transverse bead from 500 mm width.

Type	Width mm	Plate thickness mm	Length mm	Pack. m	Weight kg/100 m	Item No.
DRLU 100 FS	100	0,75	3000	3	98,670	6052103
DRLU 150 FS	150	0,75	3000	3	138,000	6052153
DRLU 200 FS	200	1	3000	3	177,670	6052210
DRLU 300 FS	300	1	3000	3	255,670	6052307
DRLU 400 FS	400	1	3000	3	334,670	6052405
DRLU 500 FS	500	1,25	3000	3	619,500	6052512
DRLU 600 FS	600	1,25	3000	3	737,340	6052609
DRLU 100 DD	100	0,75	3000	3	89,000	6052643
DRLU 150 DD	150	0,75	3000	3	138,340	6052647
DRLU 200 DD	200	1	3000	3	177,670	6052650
DRLU 300 DD	300	1	3000	3	256,000	6052656
DRLU 400 DD	400	1	3000	3	334,470	6052662
DRLU 500 DD	500	1,25	3000	3	619,340	6052668
DRLU 600 DD	600	1,25	3000	3	737,270	6052674
DRLU 050 VA4301	50	1	3000	3	59,670	6052821
DRLU 100 VA4301	100	1	3000	3	99,000	6052824
DRLU 150 VA4301	150	1	3000	3	138,000	6052828
DRLU 200 VA4301	200	1	3000	3	177,670	6052831
DRLU 300 VA4301	300	1	3000	3	256,000	6052834
DRLU 400 VA4301	400	1	3000	3	334,670	6052837
DRLU 500 VA4301	500	1,25	3000	3	516,000	6052841
DRLU 600 VA4301	600	1,25	3000	3	737,270	6052844
DRLU 050 VA4571	50	1	3000	3	59,670	6052978
DRLU 100 VA4571	100	1	3000	3	99,000	6052991
DRLU 150 VA4571	150	1	3000	3	138,000	6052992
DRLU 200 VA4571	200	1	3000	3	177,670	6052993
DRLU 300 VA4571	300	1	3000	3	256,000	6052994
DRLU 400 VA4571	400	1	3000	3	334,670	6052995
DRLU 500 VA4571	500	1,25	3000	3	619,500	6052996
DRLU 600 VA4571	600	1,25	3000	3	737,270	6052998

St Steel **V2A** Stainless steel, grade 304 **V4A** Stainless steel, grade 316 Ti

FS Strip-galvanised **DD** Strip galvanised zinc/aluminium, Double Dip