

**CHALFANT**


# NEXT DAY TRAY

## Aluminum Ladder Tray - 2A

Ladder Tray	
Item Number	Description
2A12010-09	12" Tray, 09" Rung Spacing, 12' Long
2A24010-09	24" Tray, 09" Rung Spacing, 12' Long

Accessories	
Item Number	Description
2ASP200	4 Bolt Splice Plate
2ASP212	Vertical Adjustable Splice Plate

Fittings	
Item Number	Description
2A12032	12" 90° Horizontal Bend 24" Radius
2A12052	12" 90° Outside Vertical Bend 24" Radius
2A12072	12" 90° Inside Vertical Bend 24" Radius
2A12082	12" Cross 24" Radius
2A12087	12" Tee 24" Radius
2A24032	24" 90° Horizontal Bend 24" Radius
2A24052	24" 90° Outside Vertical Bend 24" Radius
2A24072	24" 90° Inside Vertical Bend 24" Radius
2A24082	24" Cross 24" Radius
2A24087	24" Tee 24" Radius

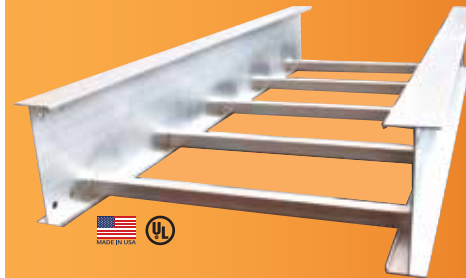

### Program Details:

The Next Day Tray program is limited to the program literature's items.

Purchase Orders must be marked "NDT2021" to qualify.

The following maximum order quantities apply to the program:

- 50 Pieces for Straight Sections
- 5 Horizontal Tee Fittings
- 5 Horizontal Cross Fittings
- 10 Horizontal Bend Fittings
- 10 Vertical Bend Fittings

Orders over 50 straight sections will ship first 50 pieces within 24-hours, and the remaining balance within 5-7 business days. Pricing is subject to change without notice. Orders over \$5,000 ship pre-paid. Next Day Tray is subject to availability.

Chalfant Standard Terms and Conditions apply. Contact your local sales rep for additional details.

## Aluminum Ladder Tray - 46A

Ladder Tray	
Item Number	Description
46A12010-09	12" Tray, 09" Rung Spacing, 12' Long
46A24010-09	24" Tray, 09" Rung Spacing, 12' Long

Accessories	
Item Number	Description
46ASP212	Vertical Adjustable Splice Plate
46ASP200	4 Bolt Splice Plate

Fittings	
Item Number	Description
46A12032	12" 90° Horizontal Bend 24" Radius
46A12052	12" 90° Outside Vertical Bend 24" Radius
46A12072	12" 90° Inside Vertical Bend 24" Radius
46A12082	12" Cross 24" Radius
46A12087	12" Tee 24" Radius
46A24032	24" 90° Horizontal Bend 24" Radius
46A24052	24" 90° Outside Vertical Bend 24" Radius
46A24072	24" 90° Inside Vertical Bend 24" Radius
46A24082	24" Cross 24" Radius
46A24087	24" Tee 24" Radius

## Ladder Tray Accessories

Clamps	
Item Number	Description
9ABC250	Hold Down Clamp
9AEX253	Expansion Guide Clamp
9SHC249	2A Hanger Rod Clamp
9SHC257	46A Hanger Rod Clamp

Trapeze	
Item Number	Description
9S18323	12-Inch Wide Tray Trapeze Bracket
9S30323	24-Inch Wide Tray Trapeze Bracket



(330) 273-3510



www.chalfant-obo.com



1050 Jaycox Road  
Avon, Ohio 44011

## GR-Magic®

### Wire Mesh Cable Tray

Article/Ref.ID	Item Number	Description
6001442	WMGR204S	2"x4"x10' Mesh Cable Tray GRM G
6001444	WMGR206S	2"x6"x10' Mesh Cable Tray GRM G
6002402	WMGR404S	4"x4"x10' Mesh Cable Tray GRM G
6002406	WMGR406S	4"x6"x10' Mesh Cable Tray GRM G
6002404	WMGR408S	4"x8"x10' Mesh Cable Tray GRM G
6002408	WMGR412S	4"x12"x10' Mesh Cable Tray GRM G
6002413	WMGR418S	4"x18"x10' Mesh Cable Tray GRM G
6002417	WMGR424S	4"x24"x10' Mesh Cable Tray GRM G

### Accessories

#### Light Duty Wall Brackets


Article/Ref.ID	Item Number	Description
6420606	AWG1511FT	Light Duty Wall Bracket, 4-inch, Quick-Connect
6420607	AWG1516FT	Light Duty Wall Bracket, 6-inch, Quick-Connect
6420608	AWG1521FT	Light Duty Wall Bracket, 8-inch, Quick-Connect
6420610	AWG1531FT	Light Duty Wall Bracket, 12-inch, Quick-Connect
6420612	AWG1541FT	Light Duty Wall Bracket, 16-inch, Quick-Connect
6420614	AWG1551FT	Light Duty Wall Bracket, 20-inch, Quick-Connect
6420616	AWG1561FT	Light Duty Wall Bracket, 24-inch, Quick-Connect

#### Barriers and Mounting Hardware

Article/Ref.ID	Item Number	Description
6015276	WMHDC38S	Hold Down Clamp 3/8" diameter (50/pack)
6016596	WMTB620S	Tee Bolt Assembly (20/pack)
6016696	WMGCLIPLG	Bonding Clamp For 8"- 24" Tray
6016994	WMCLIPSM	Bonding Clamp For 2" - 6" Tray
6062033	WMBS118-2S	2-inch Tool Free Magic Barrier (Use with WMBSM-T Barrier Strips)
6062114	WMBS118-4S	4-inch Tool Free Magic Barrier (Use with WMBSM-T Barrier Strips)
6062282	WMBSM-T	Hold Down Clamp for Barrier Strip (30/pack)
6404014	WMGC-00	Bonding Lug - 10ga. SOL - 1/0ga. STR
6017371K	WM90BKG	90-Deg Splice Kit for constructing 90's, Tees, & Crosses

#### Tab Profile Brackets

Item Number	Description
WM04323-3/8	Universal Tab-Loc Magic Trapeze/Center Bracket 4-inch with hardware
WM06323-3/8	Universal Tab-Loc Magic Trapeze/Center Bracket 6-inch with hardware
WM08323-3/8	Universal Tab-Loc Magic Trapeze/Center Bracket 8-inch with hardware
WM12323-3/8	Universal Tab-Loc Magic Trapeze/Center Bracket 12-inch with hardware
WM18323-3/8	Universal Tab-Loc Magic Trapeze/Center Bracket 18-inch with hardware
WM24323-3/8	Universal Tab-Loc Magic Trapeze/Center Bracket 24-inch with hardware

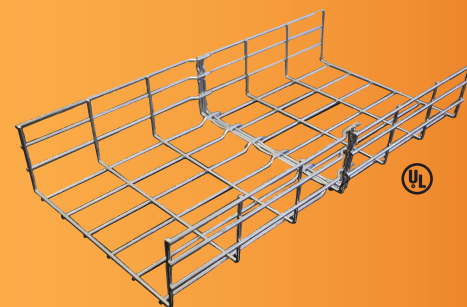

The GR-Magic® Wire Mesh Cable Tray is a patented self-connecting wire mesh tray solution. The innovative, self-connecting "Magic" ends allow installers to connect tray lengths in a single snap. **SET. SNAP. DONE.**

#### Program Details:

The Next Day Tray program is limited to the program literature's items.

Purchase Orders must be marked "NDT2021" to qualify.

The following maximum order quantities apply to the program:

- 50 Pieces for Straight Sections
- 5 Horizontal Tee Fittings
- 5 Horizontal Cross Fittings
- 10 Horizontal Bend Fittings
- 10 Vertical Bend Fittings

Orders over 50 straight sections will ship first 50 pieces within 24-hours, and the remaining balance within 5-7 business days. Pricing is subject to change without notice. Orders over \$5,000 ship pre-paid. Next Day Tray is subject to availability.

Chalfant Standard Terms and Conditions apply. Contact your local sales rep for additional details.

Email [orders@chalfant-obo.com](mailto:orders@chalfant-obo.com) to start your order

# CHALFANT

OBO Bettermann Group

© 2021 Chalfant Manufacturing Company. All rights reserved

4/21 Rev.1



(330) 273-3510



www.chalfant-obo.com



1050 Jaycox Road  
Avon, Ohio 44011